

# TRA56– Period Pole Mount Arm

TYPE



TRA56

1. ARM

2. COLOR

## 1. ARM

TRA56 (Single arm. Weight: 8 lbs. EPA: .54)

## 2. COLOR


- BLS** Black Gloss Smooth
- BLT** Black Matte Textured
- DBS** Dark Bronze Gloss Smooth
- DBT** Dark Bronze Matte Textured
- GTT** Graphite Matte Textured
- LGS** Light Grey Gloss Smooth
- LGT** Light Grey Matte Textured
- PSS** Platinum Silver Smooth
- VGT** Verde Green Textured
- WHS** White Gloss Smooth
- WHT** White Matte Textured

### Color Option

**CC\*** Custom Color

\* Consult factory for custom color, marine and corrosive finish options

## DIMENSIONS

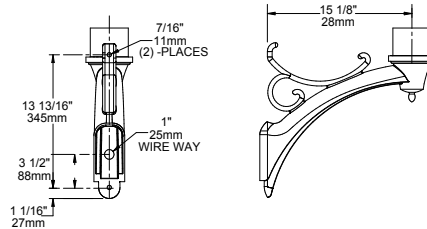

TRA56 (4" or 5" pole)

## SPECIFICATIONS

The arm shall be one piece cast aluminum construction. The arm shall be prewired with a quick connector for easy installation.

The arm shall have a cast aluminum fitter welded to the top of the arm(s) for attaching the fixture. The fixture shall be mounted with three stainless steel bolts through the top of the arm fitter into the fixture. The attachment point shall have a silicone pad for sealing the fixture to arm connection.

The arm shall bolt to a 4"/100mm diameter pole.

**NOTE:** Arm can be ordered for a 5" o.d. pole.

**JOB** \_\_\_\_\_  
**TYPE** \_\_\_\_\_  
**NOTES** \_\_\_\_\_  
 \_\_\_\_\_



ARCHITECTURAL AREA LIGHTING  
 17760 Rowland Street | City of Industry | CA 91748  
 P 626.968.5666 | F 626.369.2695 | www.aal.net  
 Copyright © 2016 November 9, 2020 7:23 PM