


TRA59U/TRA59D – Traditional Pole Mount Arms

TYPE

For Providence Small (PROS) Arms Only

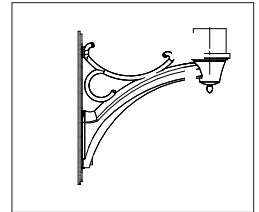

TRA59U

1. ARM

2. COLOR

1. ARM

TRA59U – Pole mount up (Weight: 3.35 lbs. EPA: .16)

TRA59D – Pole mount down (Weight: 3.35 lbs. EPA: .13)

2. COLOR


- BLS** Black Gloss Smooth
- BLT** Black Matte Textured
- DBS** Dark Bronze Gloss Smooth
- DBT** Dark Bronze Matte Textured
- GTT** Graphite Matte Textured
- LGS** Light Grey Gloss Smooth
- LGT** Light Grey Matte Textured
- PSS** Platinum Silver Smooth
- VGT** Verde Green Textured
- WHS** White Gloss Smooth
- WHT** White Matte Textured

Color Option


CC* Custom Color

* Consult factory for custom color, marine and corrosive finish options

DIMENSIONS

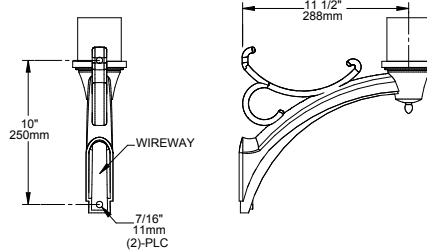

TRA59U

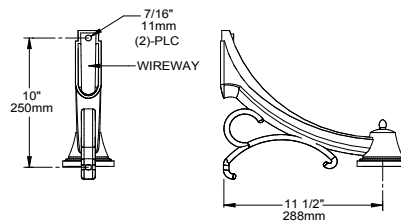

TRA59D

SPECIFICATIONS

The arm shall be one piece cast aluminum construction. The arm shall be prewired with a quick connector for easy installation.

The fixture shall be mounted with three stainless steel set screws through the top of the arm filter into the fixture. The attachment point shall have a silicone pad for sealing the fixture to arm connection.

The arm shall bolt to a 4"/100mm diameter pole.

JOB _____
 TYPE _____
 NOTES _____



ARCHITECTURAL AREA LIGHTING
 17760 Rowland Street | City of Industry | CA 91748
 P 626.968.5666 | F 626.369.2695 | www.aal.net
 Copyright © 2016 November 9, 2020 7:22 PM