



TRA6D

1. ARM

2. COLOR

1. ARM

TRA6U (Mount up. Weight: 9 lbs. EPA: .62)  
TRA6D (Mount down. Weight: 9 lbs. EPA: .62)

2. COLOR


- BLS Black Gloss Smooth
- BLT Black Matte Textured
- DBS Dark Bronze Gloss Smooth
- DBT Dark Bronze Matte Textured
- GTT Graphite Matte Textured
- LGS Light Grey Gloss Smooth
- LGT Light Grey Matte Textured
- PSS Platinum Silver Smooth
- VGT Verde Green Textured
- WHS White Gloss Smooth
- WHT White Matte Textured

Color Option


CC\* Custom Color

\* Consult factory for custom color, marine and corrosive finish options

DIMENSIONS

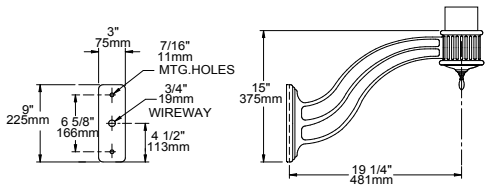

TRA6U (4" or 5" pole)

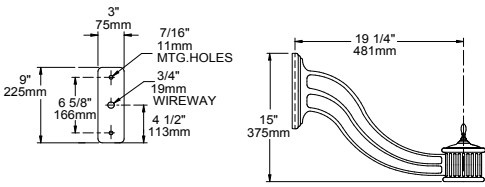

TRA6D (4" or 5" pole)

SPECIFICATIONS

The arm shall be one piece cast aluminum construction. The arm shall be prewired with a quick connector for easy installation.

The arm shall have a cast aluminum fitter welded to the top of the arm(s) for attaching the fixture. The fixture shall be mounted with three stainless steel bolts through the top of the arm fitter into the fixture. The attachment point shall have a silicone pad for sealing the fixture to arm connection.

The arm shall bolt to a 4"/100mm O.D. pole.

Note: Fixture type and mounting orientation will determine size of arm tail.

JOB \_\_\_\_\_

TYPE \_\_\_\_\_

NOTES \_\_\_\_\_

