

DATE: \_\_\_\_\_ LOCATION: \_\_\_\_\_

TYPE: \_\_\_\_\_ PROJECT: \_\_\_\_\_

CATALOG #: \_\_\_\_\_

# OCR-03L Series

DECORATIVE OUTDOOR REMOTE LIGHTING HEADS

## FEATURES

Outdoor UL Wet Location Listed die-cast aluminum lamp head and mounting plate assembly complete with LED MR16 lamp. Single or twin lamp fixtures available in dark bronze, black or white polyester powder coat finish. Mounts to 3½" octagonal or single gang boxes. Available with 3-watt LED lamps.

## ORDERING GUIDE

Example: OCRSB-03L

CATALOG #



OCR	Heads	Finish	Lamp
OCR	S Single D Double	W White B Black Z Dark Bronze	03L 6/12V, 3W LED MR16



## RELATED PRODUCTS

[HCX Series Combination Exit/Emergency Light](#)

## APPLICATION INFORMATION

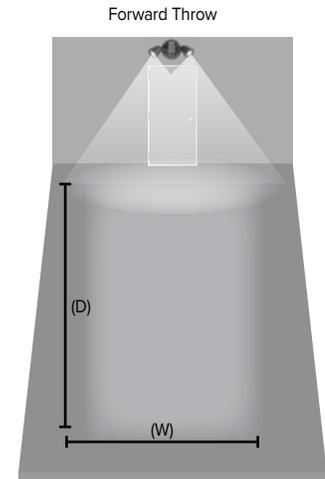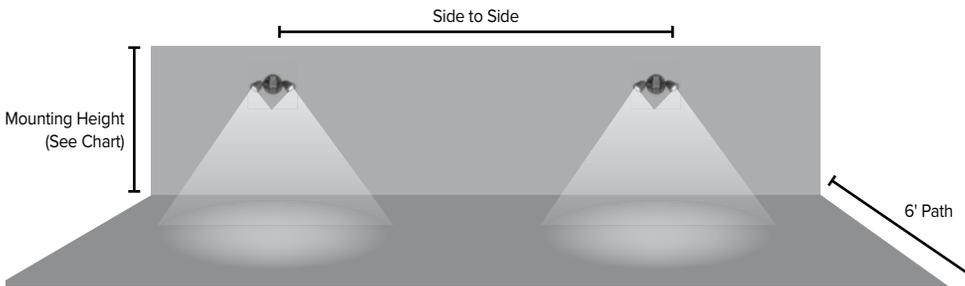

OCR-03L Multi double-head unit	Side to Side	
1fc avg.	Depth	Width
7.5' Mounting Height	48'	6'
9.0' Mounting Height	42'	6'

OCR-03L One double-head unit	Forward Throw	
1fc avg.	Depth	Width
7.5' Mounting Height	27	10'
9.0' Mounting Height	23	10'

1fc min.	Depth	Width
7.5' Mounting Height	22'	6'
9.0' Mounting Height	25'	6'

1fc min.	Depth	Width
7.5' Mounting Height	7	10'
9.0' Mounting Height	9	10'


Meets Life Safety Code minimum illuminance of 0.1 fc and average illuminance of 1.0 fc. Assumes open space with no obstructions, mounting height of 7.5', ceiling height of 9' and reflectances of 80/50/20. Photometry files available on the Dual-Lite website ([www.Dual-lite.com](http://www.Dual-lite.com)).

## PHOTOMETRY

### LUMINAIRE DATA

Test No.	P22.00079
Description	Remote Emergency Head
Watts	2.6
Efficacy	96.9 lm/W
Mounting	Surface

### POLAR GRAPH

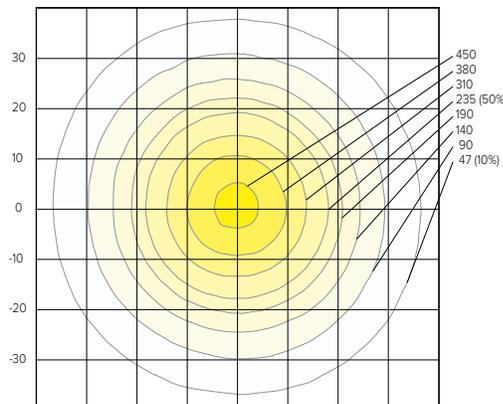

DATE: \_\_\_\_\_ LOCATION: \_\_\_\_\_

TYPE: \_\_\_\_\_ PROJECT: \_\_\_\_\_

CATALOG #: \_\_\_\_\_

# CPR-03L

DECORATIVE INDOOR REMOTE LIGHTING HEADS

## FEATURES

Injection molded thermoplastic decorative lamphead and mounting plate assembly. Mounts to 3½" octagonal or single gang boxes. Single and twin lamp fixtures with LED MR16 lamp included. Available in white finish.

## ORDERING GUIDE

Example: CPRSW-03L

CATALOG #

AHD						
Model	Heads	Finish	Lamp			
CPR	S	Single	W	White	-03L	6V/12V, 3W LED MR16 Lamp
	D	Double				



## RELATED PRODUCTS

[Ø HCX Combination Exit/Emergency Light](#)

## Other Remotes REFER TO PRODUCT SPECIFIC PAGES


DATE: \_\_\_\_\_ LOCATION: \_\_\_\_\_

TYPE: \_\_\_\_\_ PROJECT: \_\_\_\_\_

CATALOG #: \_\_\_\_\_

# AHD Series

ALL METAL REMOTE LIGHTING HEADS

## FEATURES

Stamped aluminum housing with metal swivel. Standard finish available in white or black. Choice of incandescent or halogen PAR 36 lamps.

## ORDERING GUIDE

Example: AHDSW0612

CATALOG #



AHD			
Model	Heads	Finish	Lamp
AHD	S Single	W White	0605 6 volt, 5.4 watts Incandescent <sup>1</sup>
		B Black	0607 6 volt, 7.2 watts Incandescent 0608 6 volt, 8 watts Halogen <sup>1</sup>
	D Double	W White	0612 6 volt, 12 watts Halogen
		B Black	0618 6 volt, 18 watts Incandescent 0620 6 volt, 20 watts Halogen
			0625 6 volt, 25 watts Incandescent
			1207 12 volt, 7.2 watts Incandescent 1208 12 volt, 8 watts Halogen <sup>1</sup>
			1212 12 volt, 12 watts Halogen
			1218 12 volt, 18 watts Incandescent 1225 12 volt, 25 watts Incandescent
			1235 12 volt, 35 watts Incandescent
			1250 12 volt, 50 watts Halogen

## RELATED PRODUCTS

[LM Series](#)

Notes:

- 1 Sealed Beam Type Lamp

# SRH Series

STANDARD REMOTE LIGHTING HEADS

## FEATURES

Injection molded thermoplastic lamphead/round mounting plate assemblies. Mounts to 3½" octagonal or single gang boxes. For use with most commercial or industrial emergency fixtures. Standard finish is available in white or black. Single and twin lamp fixtures with a choice of incandescent or halogen PAR 36 lamps.

## ORDERING GUIDE

Example: AHDSW0612

CATALOG #



SRH			
Model	Heads	Finish	Lamp
SRH	S Single	W White	0605 6 volt, 5.4 watts Incandescent <sup>1</sup>
		B Black	0607 6 volt, 7.2 watts Incandescent 0608 6 volt, 8 watts Halogen <sup>1</sup>
	D Double	W White	0612 6 volt, 12 watts Halogen
		B Black	0618 6 volt, 18 watts Incandescent 0620 6 volt, 20 watts Halogen
			0625 6 volt, 25 watts Incandescent
			1207 12 volt, 7.2 watts Incandescent 1208 12 volt, 8 watts Halogen <sup>1</sup>
			1212 12 volt, 12 watts Halogen
			1218 12 volt, 18 watts Incandescent 1225 12 volt, 25 watts Incandescent
			1235 12 volt, 35 watts Incandescent
			1250 12 volt, 50 watts Halogen

## RELATED PRODUCTS

[LM Series](#)

Notes:

- 1 Sealed Beam Type Lamp

DATE: \_\_\_\_\_ LOCATION: \_\_\_\_\_

TYPE: \_\_\_\_\_ PROJECT: \_\_\_\_\_

CATALOG #: \_\_\_\_\_

# OMS Series

OUTDOOR REMOTE LIGHTING HEADS

## FEATURES

Outdoor aluminum spot with sealed lamp and swivel assembly. Furnished with round gasketed aluminum mounting plate. Mounts to 3 1/2" octagonal boxes.



## ORDERING GUIDE

Example: OMSDB0605

CATALOG #

OMS				
Model	Heads	Finish	Lamp	
OMS	S Single D Double	W White B Black	0605	6 volt, 5.4 watts Incandescent <sup>1</sup>
			0607	6 volt, 7.2 watts Incandescent <sup>1</sup> 0608 6 volt, 8 watts Halogen <sup>1</sup>
			0612	6 volt, 12 watts Halogen
			0618	6 volt, 18 watts Incandescent 0620 6 volt, 20 watts Halogen
			0625	6 volt, 25 watts Incandescent
			1207	12 volt, 7.2 watts Incandescent <sup>1</sup> 1208 12 volt, 8 watts Halogen <sup>1</sup>
			1212	12 volt, 12 watts Halogen
			1218	12 volt, 18 watts Incandescent 1225 12 volt, 25 watts Incandescent
			1235	12 volt, 35 watts Incandescent
			1250	12 volt, 50 watts Halogen

## RELATED PRODUCTS

[LM Series](#)

Notes:

1 Sealed Beam Type Lamp