

WALL OR CEILING MOUNT

EUROLUXE® SERIES

Cat.#

Job

Type



HUBBELL
Outdoor Lighting

Approvals

Intended Use

- Several colors and accessories, including guards and shields, are available for both interior and exterior applications, such as entry, perimeter, walls, stairwells, corridors, etc.

Construction


- Borosilicate glass lens sealed to housing by silicone gasket and stainless steel philips head screws; Ribbed lens uniformly spreads light for a symmetrical, soft distribution
- Die cast aluminum housing and face trims
- Two point lag or hickey mount to recessed junction box
- Dark bronze, Black and White finishes are offered

Electrical


- BRLU LED has 6 LED in 15w, 120-277V, 830 lumens, 5000K, 700mA

Listings

- Listed to UL1598 for use in wet locations

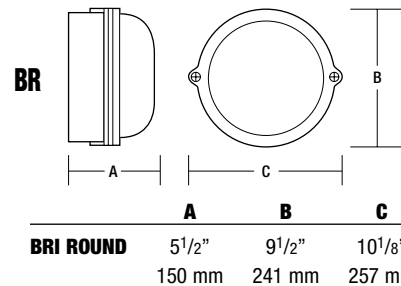

 ORDERING INFORMATION ORDERING EXAMPLE: BOI-01



Catalog Number	Shape	Finish	Wattage	Weight	
				lbs.	kg
LED¹					
BRLU-01	Round	Bronze	15 max.	6.0	2.7
BRLU-04	Round	White	15 max.	6.0	2.7

ACCESSORIES

(order as separate part #)

Catalog Number	Description
BR-GX¹	Cast aluminum guard for round fixture
BR-SX¹	Cast aluminum shield for round fixture

¹ Finish must be specified, substitute **X** for: **1**-bronze, **2**-black, **4**-white



SHIELD

GUARD



HUBBELL
Outdoor Lighting

Hubbell Outdoor Lighting • 701 Millennium Boulevard • Greenville, SC 29607 • Phone: 864-678-1000

Due to our continued efforts to improve our products, product specifications are subject to change without notice.

© 2015 HUBBELL OUTDOOR LIGHTING, All Rights Reserved • For more information visit our website: www.hubbelloutdoor.com • Printed in USA

BR-SPEC 6/17