


JAWS SERIES AUTOSPLICE

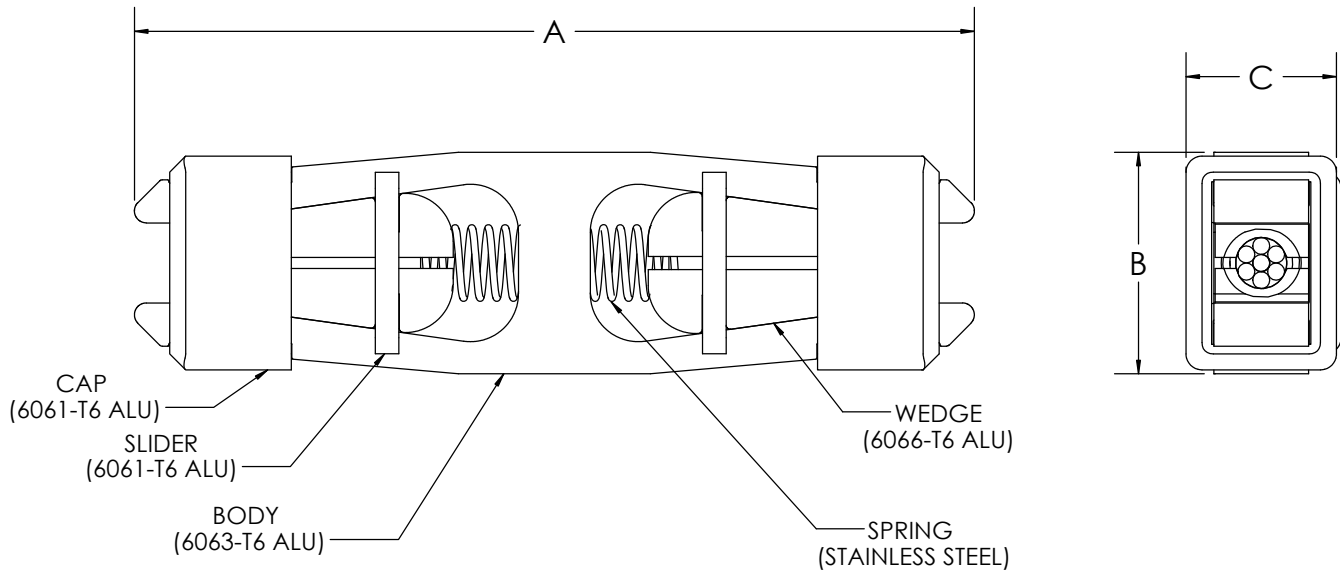

Catalog #	Conductor Range		Dimensions		
	Description	Diameter	A	B	C
S500	#6AAC/ACSR/AAC #4AAC/ACSR/AAC	.184" - .257"	6.5"	1.75"	1.25"
S750	#4ACSR/AAC/AAC #2AAC/ACSR/AAC	.250" - .316"	6.5"	1.75"	1.25"
S1000	#2AAC/ACSR/AAC 1/0AAC/ACSR/AAC 2/0AAC	.292" - .414"	6.5"	1.75"	1.25"
S2000	3/0AAC/ACSR/AAC 4/0AAC/ACSR/AAC 266.8AAC	.464" - .586"	8.625"	2.437"	1.5"
S3000	266.8ACSR/AAC 336.4AAC/ACSR 18/1AAC 397.5AAC/ACSR 18/1	.609" - .743"	12.375"	3.0"	1.937"
S4000	397.5 ACSR 18/1 477 ACSR 26/7 556.5 AAC	.743" - .858"	11"	3.0"	1.75"

Standard Package			
Part #	Quantity.	Dimension	Weight lbs.
S500, S750, S1000	50	11"x11"x7"	32
S2000	20	11"x11"x7"	32
S3000	15	14"x9"x9"	52
S4000	12	11"x11"x7"	38