

MICROLITER[®] SERIES

Cat.#

Job

Type



HUBBELL
Outdoor Lighting

Approvals

APPLICATIONS

- Signs, facades, small area illumination, flag poles and landscape accent

SPECIFICATIONS

- Die cast aluminum housing is rugged, yet lightweight and compact in size
- The die cast aluminum door hinges and is removable for service. Two Hubbell Gard[®] screw fasteners secure the lens door to a silicone gasket for positive seal
- 1/2" cast aluminum knuckle provides universal aiming (1/2 x 14 NPS)
- Rotatable optics. Medium base lamp included
- HPS offered in 120V NPF or Multitap HPF, PSMH is HPF Multitap
- Bronze Lektrocote[®] powder paint finish


LISTINGS

- Listed to UL1598 for use in wet locations

PRODUCT IMAGE(S)



DIMENSIONS

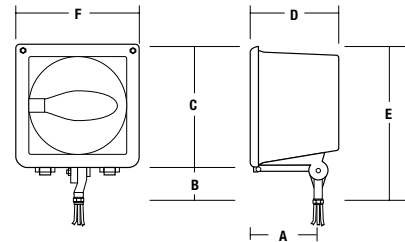

A	B	C	D	E	F
4 ⁷ / ₈ "	2 ¹ / ₂ "	9 ¹ / ₄ "	7 ³ / ₈ "	12 ¹ / ₈ "	9 ¹ / ₄ "
124 mm	64 mm	235 mm	187 mm	308 mm	235 mm

LISTINGS



ORDERING INFORMATION

Catalog Number ¹	Wattage	Photometry NEMA/IES H° x V°	Lamp Type	Voltage	Weight lbs. (kg)	EPA ft ² (m ²)	Ballast Type ²
High Power Factor, Pulse Start Metal Halide							
MIC-0150P-338¹	150	3 (32°) x 3 (36°)	Clear	120/208/240/277	14 (6.4)	0.71 (0.1)	PLA

¹ Quad-Tap[®] luminaires are shipped wired for 277V, easily changed to other voltages in the field

ACCESSORIES - Order Separately

Catalog Number	Description
MIC-GS-2	Glare shield (360°) bronze
MIC-SPC-2	Polycarbonate shield assembly
S-302-M51	Pole-top slipfitter for 1/2" knuckle, slipfits 2 3/8" OD pipe, bronze finish
PBT-1	Photocontrol, button type, 120V
TRN-XX¹	Trunnion adaptor for 1/2" threaded knuckle mount

¹ Specify color, eg. DB - Dark Bronze

REPLACEMENT PARTS

Catalog Number	Description
264-0292-9903	Lens
800-2827-0100	Bronze lens/door assembly
207-5011-0264	Bronze knuckle

