

CEILING MOUNT

NRG®400 SERIES
LUMASQUARE® I

Cat. #		Approvals
Job	Type	



APPLICATIONS


- Efficient lighting distribution and good uniformity for commercial and industrial applications, such as interior lighting for offices, lobbies, stairwells, corridors, parking garages, and storage areas. Aesthetic appearance and durable construction permit outdoor and indoor security lighting for walkways, apartments, schools, hotels, motels, and commercial building

SPECIFICATIONS

- Unique prismatic polycarbonate refractor for low brightness and even distribution.
- One-piece, injection molded, bronze polycarbonate housing. Permanent color with textured finish. Very low profile - 5 inch height. Concealed latching. Ideal for indoor and outdoor damp applications. Two point mounting for stability
- Reflector for HPS is hydroformed aluminum with Anodal® finish for maximum reflectivity. (Reflector reduces glare by shielding the arc tube from normal viewing angles.) Fluorescent reflector is aluminum with white high reflectance finish. IES Type V distribution
- HPS has Class H normal power factory reactor ballast. -40°F starting, 60 Hz, 120 volt only. Fluorescent: (2) 120V, 13W reactor ballasts (lamps instant start down to 32°F). (2) 120V, 28W reactor ballasts (lamps start down to -20°F). Lamp included. HPS is B-17 clear medium base. Fluorescent is (2) 13W twin tube, or (2) 28W 15mm Quad tube, single ended

LISTINGS

- Listed to UL1598 for damp locations indoor and outdoor

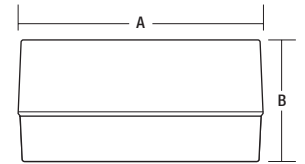

A	B
10" square 254 mm square	5" 127 mm



ORDERING INFORMATION


Catalog Number ¹	Wattage	Voltage	Ballast Type	Min. Start Temp	Input Amps	Weight lbs. (kg)
High Pressure Sodium						
NRG-401 ¹	50	120	Reactor	-40F	1.8	6 (2.7)
Fluorescent						
NRG-406-2 ¹	2 x 13	120	Preheat	32F	.7	5 (2.3)
NRG-456 ¹	2 x 28	120	NPF Reactor	-20F	1.2	6 (2.7)

¹ CSA certified for outdoor applications only; UL indoor/ outdoor, NRG-406 uses GX23 base, NRG-456 uses GX32d-3 base lamps

Note: Lamp included

ACCESSORIES - Order Separately

Catalog Number	Description
S-319-B	4" Cast aluminum round junction box for surface conduit mounting with two mounting lugs, four 1/2" tapped hubs, and three plugs; leaves fixture 2" from ceiling

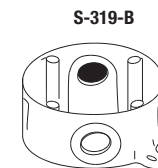

REPLACEMENT PART

Catalog Number	Description
264-0225-9904	Replacement refractor with molded hinges

PHOTOMETRIC REPORTS

Catalog Number	Report #
NRG-401	HP02075.IES
NRG-406-2	HP03243.IES
NRG-456	HP05001.IES

Due to our continued efforts to improve our products, product specifications are subject to change without notice.



Outdoor Lighting

Hubbell Outdoor Lighting • 701 Millennium Boulevard • Greenville, SC 29607 • PHONE: 864-678-1000

For more information visit our web site: www.hubbelloutdoor.com