

COR SERIES

LED Outdoor Remote

DESCRIPTION

The COR Series offers quality and value with a compact and attractive LED based remote emergency light. The white base-plate and lamp-heads are made of high impact UL flame rated thermoplastic. Lamp-heads are fully gasketed and weatherproof to ensure operation in wet environments. The lamp heads are fully adjustable and glare-free. The remote lamps are driven by the Compass remote capacity Exit, Combo or Emergency Light.

APPLICATION

The COR Series can be applied over path of egress doors and in areas affected by rain, moisture and condensation.

COMPLIANCES

NFPA 101 and NFPA 70
OSHA

WARRANTY

2 year full unit warranty



FEATURES


- Single or Double lamp-head outdoor remote with base
- LED life-cycle of more than 10 years
- Quick installation
- Fully adjustable lamp-heads
- Fully gasketed for application in wet environment

ORDERING GUIDE

Catalog Number	Description	Voltage	Lamp Watts (Each)
CORS	Single LED outdoor remote lamp-head with mounting base	3 VDC	1 Watt
CORD	Double LED outdoor remote lamp-head with mounting base	3 VDC	1 Watt

Powered by Compass Exit, Combo or Emergency Light with Remote Capacity

DIMENSIONS

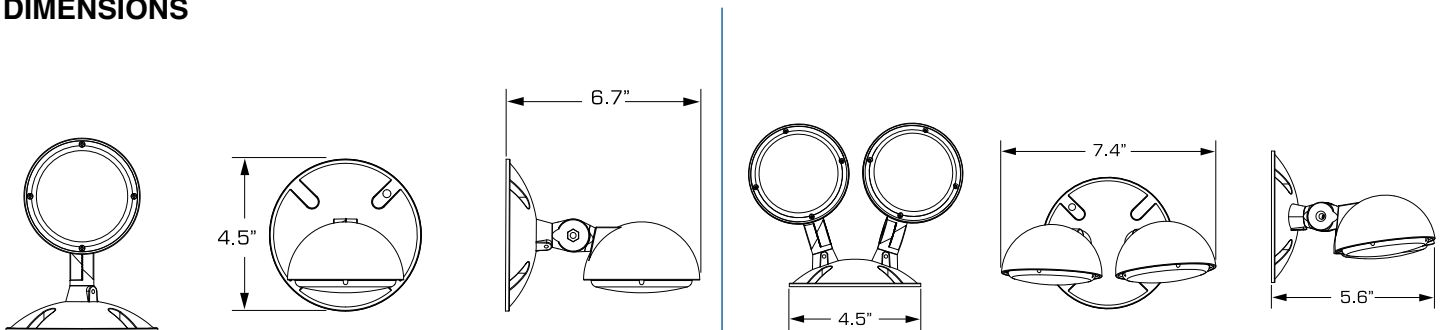

CORS

Single Remote Carton Weight: 1 lbs.
Master Carton Quantity: 20 each

CORD

Double Remote Carton Weight: 1.2 lbs.
Master Carton Quantity: 20 each