



# Revisions

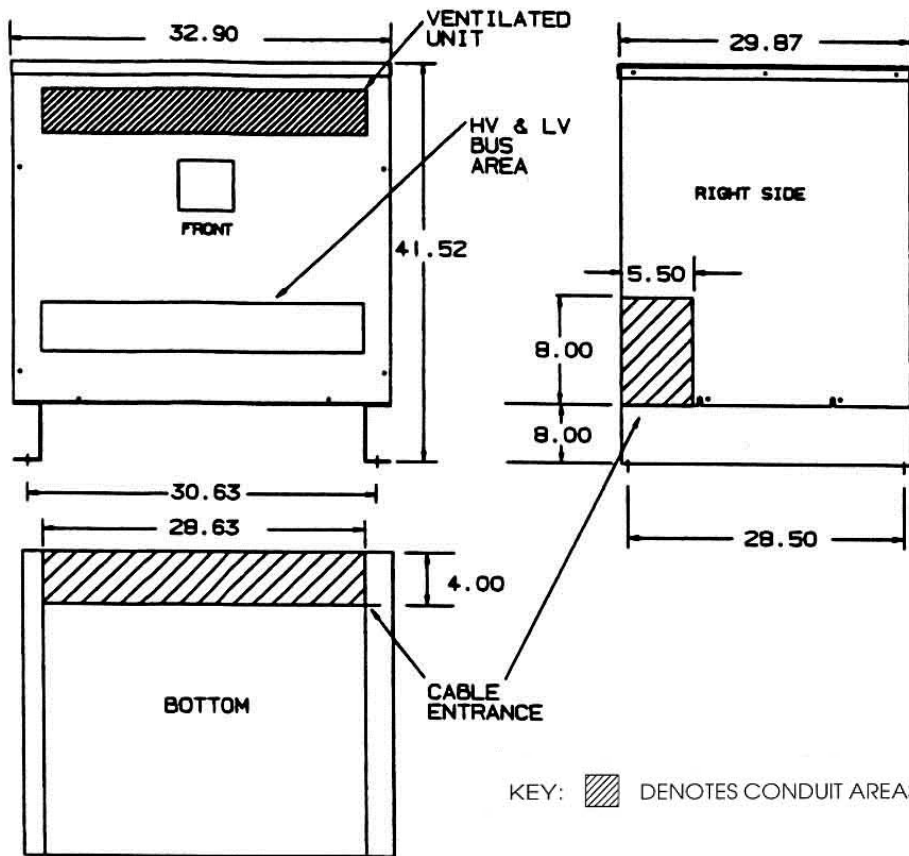

NOTE: PRIMARY AND SECONDARY BUS AREA IN FRONT OF CASE.

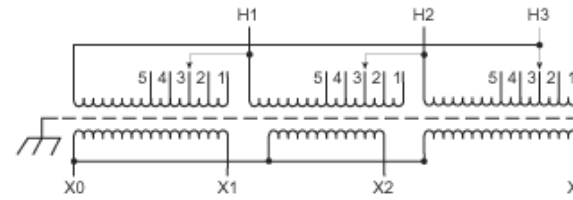

Primary Volts	%	Connect Leads to Tap No.
242	105	1
236	102.5	2
230	100	3
224	97.5	4
219	95	5
Secondary Volts		
230		X1, X2, X3
133 1 phase		X1 & X0 X2 & X0 X3 & X0

KVA	CATALOG NUMBER	VOLTAGE		WEATHER SHIELD	WEIGHT	PHASE	FREQ.
		HIGH	LOW				
175	<b>DTF A-0175-4S</b>	230Δ	230Y/133	WS-A-4	1110 Lbs	3φ	60 Hz

## TYPICAL PERFORMANCE DATA

Winding Rise	150°C
Insulation	220°C
Sound Level	55 dB

Regulation @ 100% PF	2.798%
Standards:	UL/CSA

Impedance	4.53%
-----------	-------

Typical Efficiency	98.31%
No Load Losses	617W
Full Load Losses	5,402W

Type No.

ACME ELECTRIC