


KEY: DENOTES CONDUIT AREAS

NOTE: PRIMARY AND SECONDARY BUS AREA IN FRONT OF CASE.

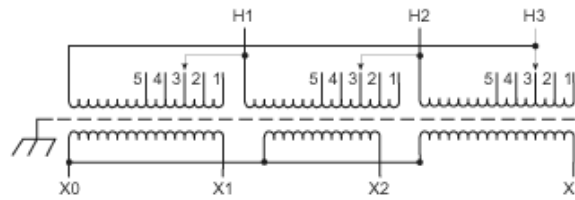

Primary Volts	%	Connect Leads to Tap No.
242	105	1
236	102.5	2
230	100	3
224	97.5	4
219	95	5
Secondary Volts		
230		X1, X2, X3
133 1 phase		X1 & X0 X2 & X0 X3 & X0

KVA	CATALOG NUMBER	VOLTAGE		WEATHER SHIELD	WEIGHT	PHASE	FREQ.
		HIGH	LOW				
93	<b>DTFA-093-4S</b>	230Δ	230Y/13	WS-A-	685 Lbs	3φ	60 Hz

TYPICAL PERFORMANCE DATA

Winding Rise	150°C	Impedance:		4.00 %	Windings:	AL	Typical Efficiency	
Insulation	220°C	Standards:		UL/CSA			No Load Losses	
Sound Level	50 dB						Full Load Losses	

ACME ELECTRIC

Type No.

						A	PRINTS TO	CONTROL	7	A
--	--	--	--	--	--	---	-----------	---------	---	---