
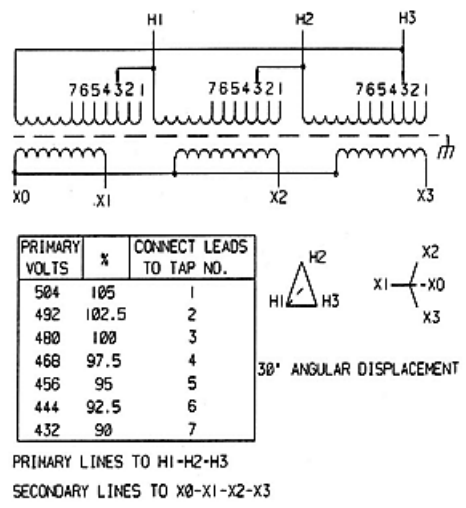


**REVISIONS**

**NOTES:**

- 1. Dry Type
- 2. Class AA
- 3. Ventilated
- 4. Paint - #61 ANSI

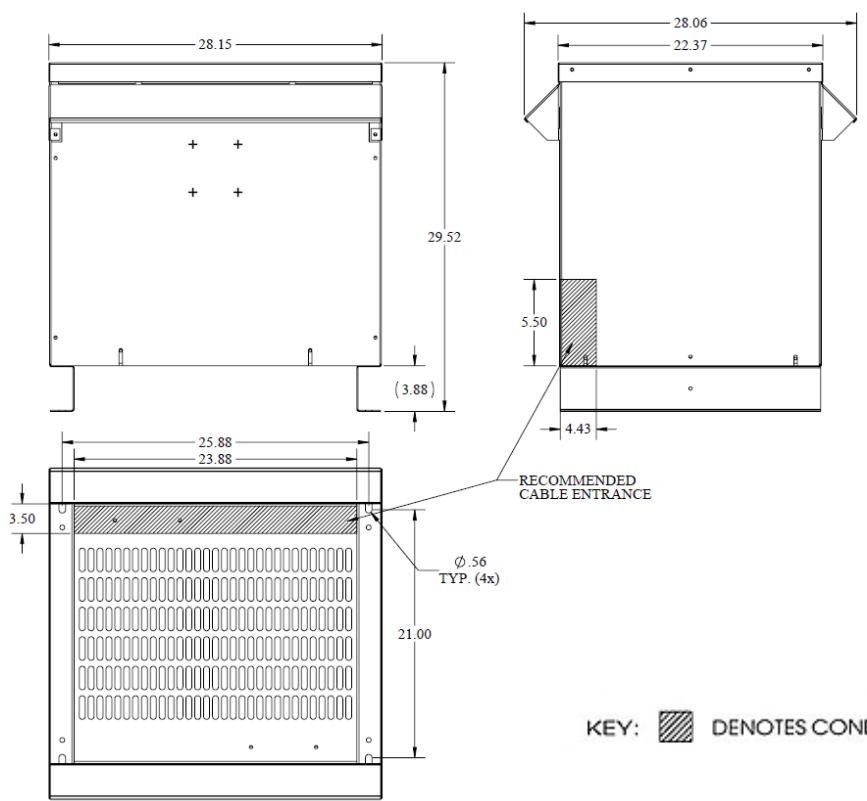

NOTE: PRIMARY AND SECONDARY BUS AREA IN FRONT OF CASE.



KVA	CATALOG NUMBER	VOLTAGE		LUG KIT	WEIGHT	PHASE	FREQUENCY
		HIGH	LOW				
75	<b>T3075K0013B</b>	480Δ	208Y/120		517 Lbs	3φ	60Hz
Temp Rise:	150°C	<b>TYPICAL PERFORMANCE DATA</b>				Typical Efficiency @ 35%	98.63%
Insulation:	220°C	Regulation @ 100% PF	2.90%	Windings:	AL	Typical No Load Losses:	153.5 W
NEMA ST20 Standard:	50 dB	Standards:	UL/CSA	Impedance:	5.86%	100% Load (Typ) Load Losses (I <sup>2</sup> R)	2,314.3 W
Electrostatic Shield:	Option	Approvals:	DOE-2016	Enclosure:	3R	Total Load Losses:	2,467.8W

DATE: 14-Aug-13

TYPE NO:

**CASE 2**

**Meets US DOE 2016 Efficiency**